


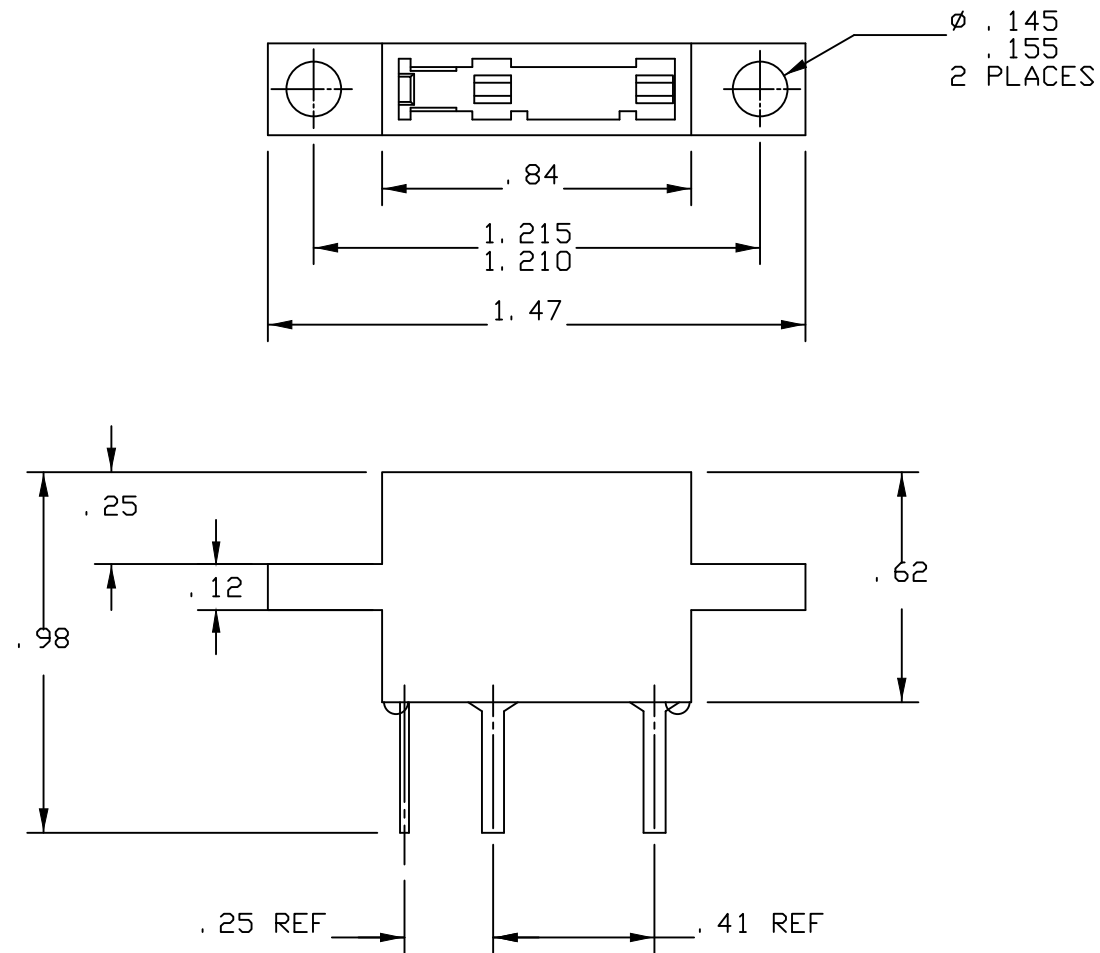

NOTES:

1. RATED AT 20 AMPERES FOR ANY VOLTAGE UP TO 125 VAC, 125 VDC.
2. MATERIAL:
BODY: BLACK THERMOPLASTIC WITH UL94V0 FLAMMABILITY RATING.
TERMINALS: BRASS, TIN-PLATED, WIRE WRAP TYPE.
3. OPERATING TEMPERATURE RANGE: -40°C TO +85°C.
4. FUSEHOLDERS ARE RECOGNIZED UNDER THE COMPONENTS PROGRAM
OF UNDERWRITERS LABORATORIES.

[illegible]