
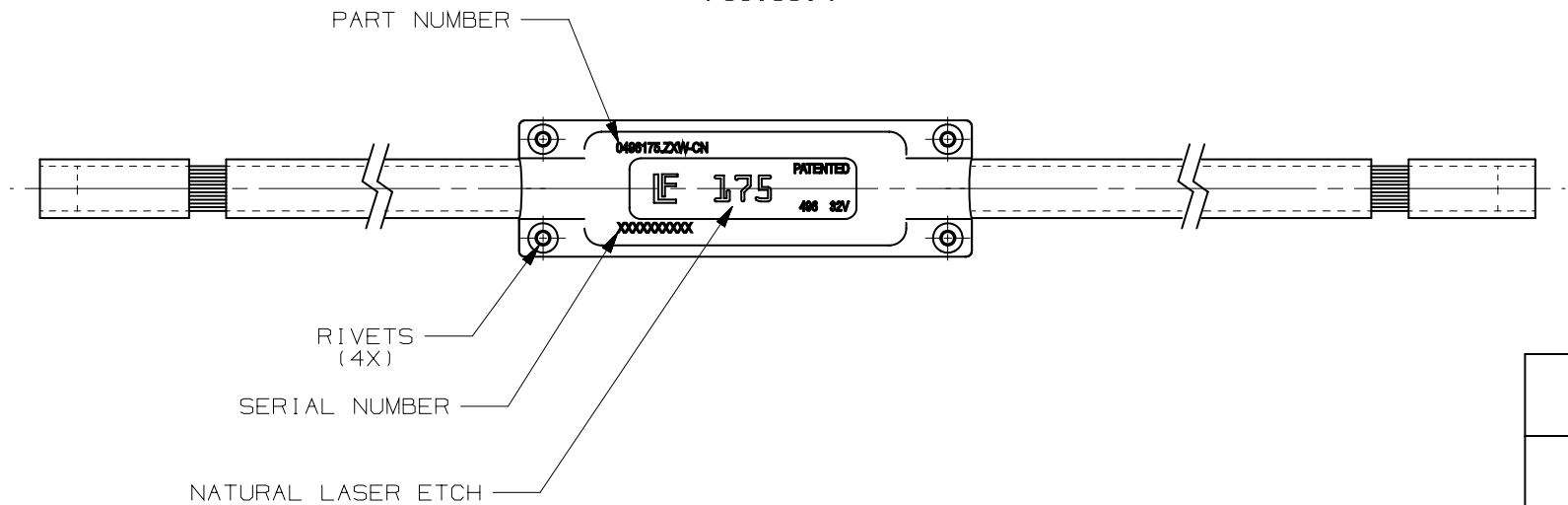
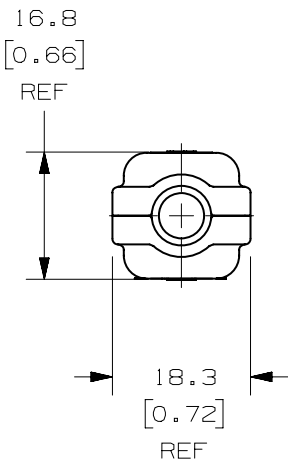


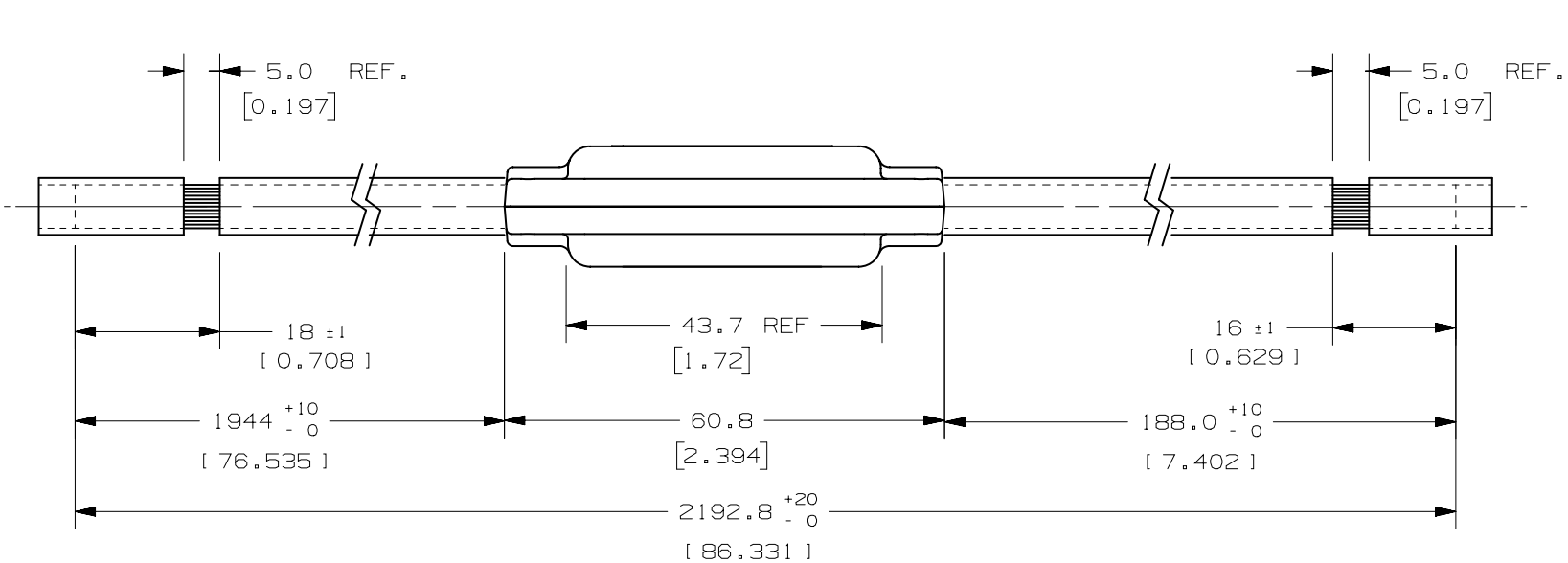

RIVETS
(4X)

SERIAL NUMBER

NATURAL LASER ETCH

% OF RATING	OPENING TIME	
	MINIMUM	MAXIMUM
100	100 HRS	-
135	120 S	1800 S
200	10 S	300 S
350	1 S	15 S
600	0.3 S	5 S

NOTES:

INTERRUPT RATING: 2000A @ 32VDC

VOLTAGE RATING: 32VDC

TEMP. RATING: -40°C - 125°C

CABLE TYPE: XLPE INSULATED, SAE J1127, STX PER M5811202 (4 GA) 125°C, RED.

SPECIFICATION: MEETS LITTELFUSE'S VS-006013 SPECIFICATION

APPLICATION: DESIGNED FOR UNDERHOOD INSTALLMENT.

SERIAL NUMBER: THE SERIAL NUMBER IS USED FOR LOT TRACEABILITY.

METRIC
ASSEMBLY

COPIES TO		MATL SPEC	
1	9	FINISH	
2	10		
3	12		
4	13	DRW OPL	SCALE FULL
5	14	CHK	SUPER DR
6	15		
7	16	APPD	FINSH GOOD WT
8	17		GRAMS/PIECE
TOLERANCES UNLESS OTHERWISE SPECIFIED (REF. ISO 2768-mK)			
DIMENSION		OVER UP TO	
TOLERANCE		OVER UP TO	
3RD ANGLE PROJECTION			
TITLE		CABLEPRO 32V 175A	
REVISION		OUTLINE	
CHK		APD	
DATE		DATE	
LTR		DATE	
A		05/09/10	
B		06/17/11	
502334ERA-RELEASE		OPL	
502632ECA-CHANGE DRWG.		OPL	
NO. FROM:			
OL-0496200.ZXW-CN TO:			
OL-0496175.ZXW-CN.			