
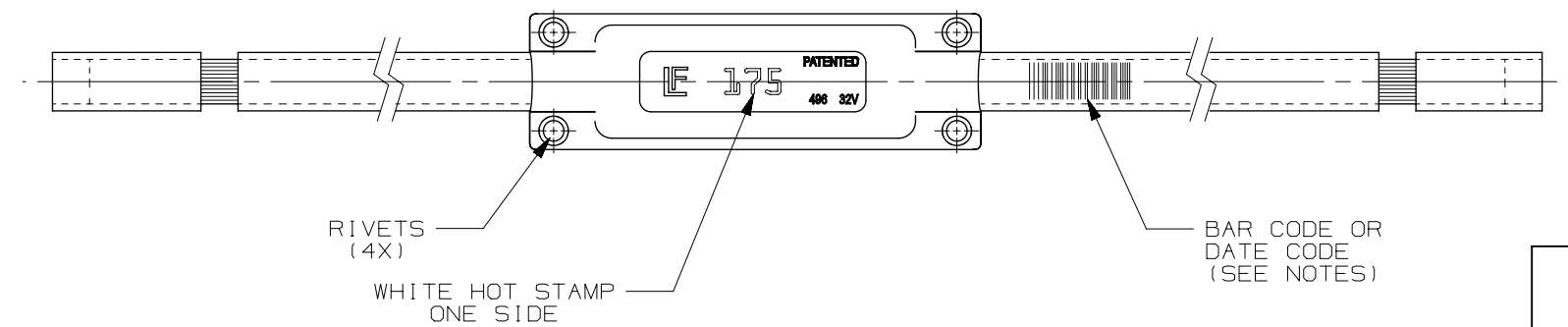
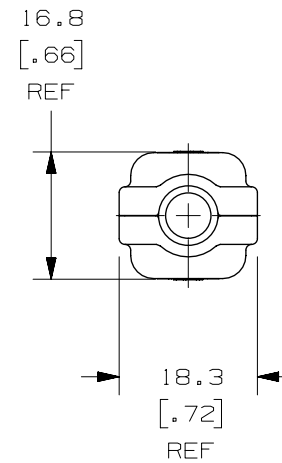


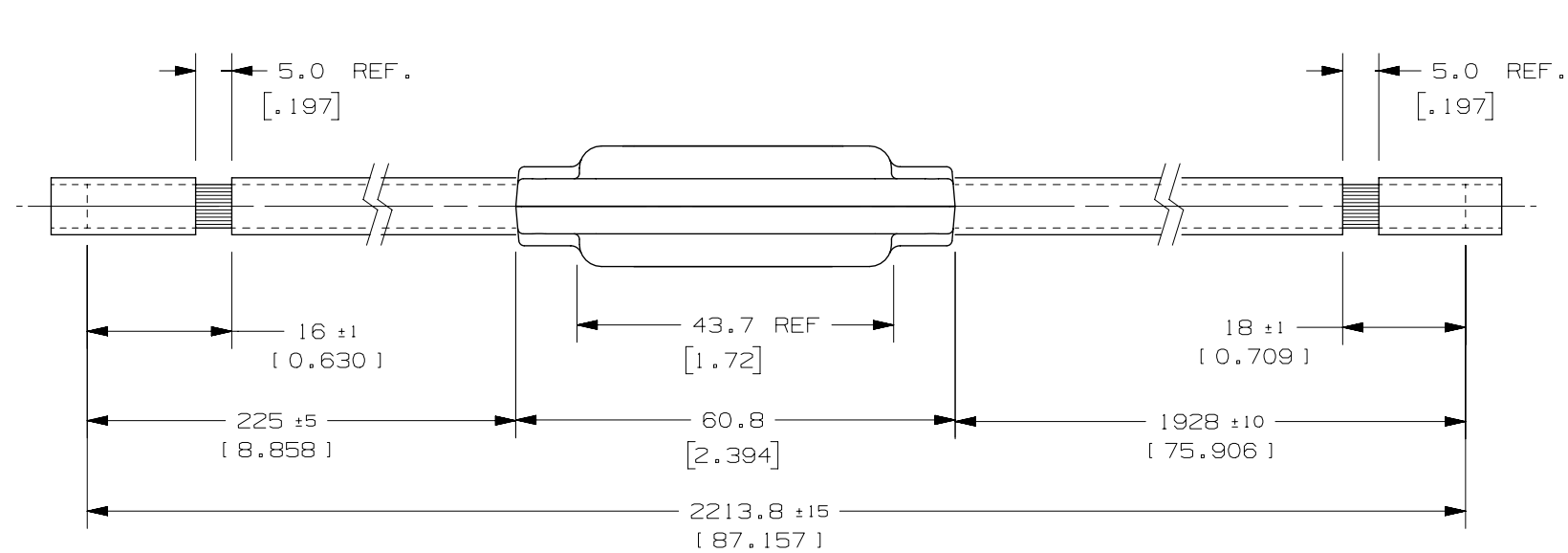

| % OF RATING | OPENING TIME |         |
|-------------|--------------|---------|
|             | MINIMUM      | MAXIMUM |
| 100         | 100 HRS      | -       |
| 135         | 120 S        | 1800 S  |
| 200         | 10 S         | 300 S   |
| 350         | 1 S          | 15 S    |
| 600         | 0.3 S        | 5 S     |

|                                                                                                                                                                                                                                                                                                                                                                                                            |     |       |
|------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------|-----|-------|
| NOTES:                                                                                                                                                                                                                                                                                                                                                                                                     | 600 | 0.3 S |
| INTERRUPT RATING: 2000A @ 32VDC<br>VOLTAGE RATING: 32VDC<br>TEMP. RATING: -40°C - 125°C<br>CABLE TYPE: XLPE INSULATED, SAE J1127, STX (4 GA) 125°C, RED.<br>SPECIFICATION: MEETS LITTELFUSE'S VS-006013 SPECIFICATION<br>APPLICATION: DESIGNED FOR UNDERHOOD INSTALLMENT.<br>BAR CODE OR<br>DATA CODE: THE BAR CODE OR DATE CODE IS USED FOR LOT TRACEABILITY.<br>IT IS LOCATED ON ONE OF THE CABLE LEADS. |     |       |

# METRIC

## ASSEMBLY

[illegible]