
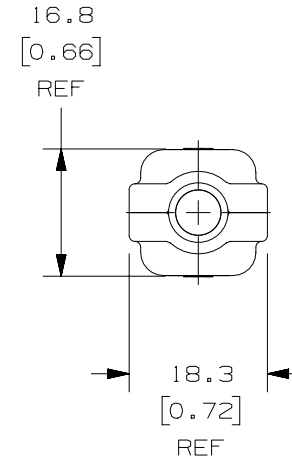


% OF RATING	OPENING TIME	
	MINIMUM	MAXIMUM
100	100 HRS	-
135	120 S	1800 S
200	10 S	300 S
350	1 S	15 S
600	0.3 S	5 S

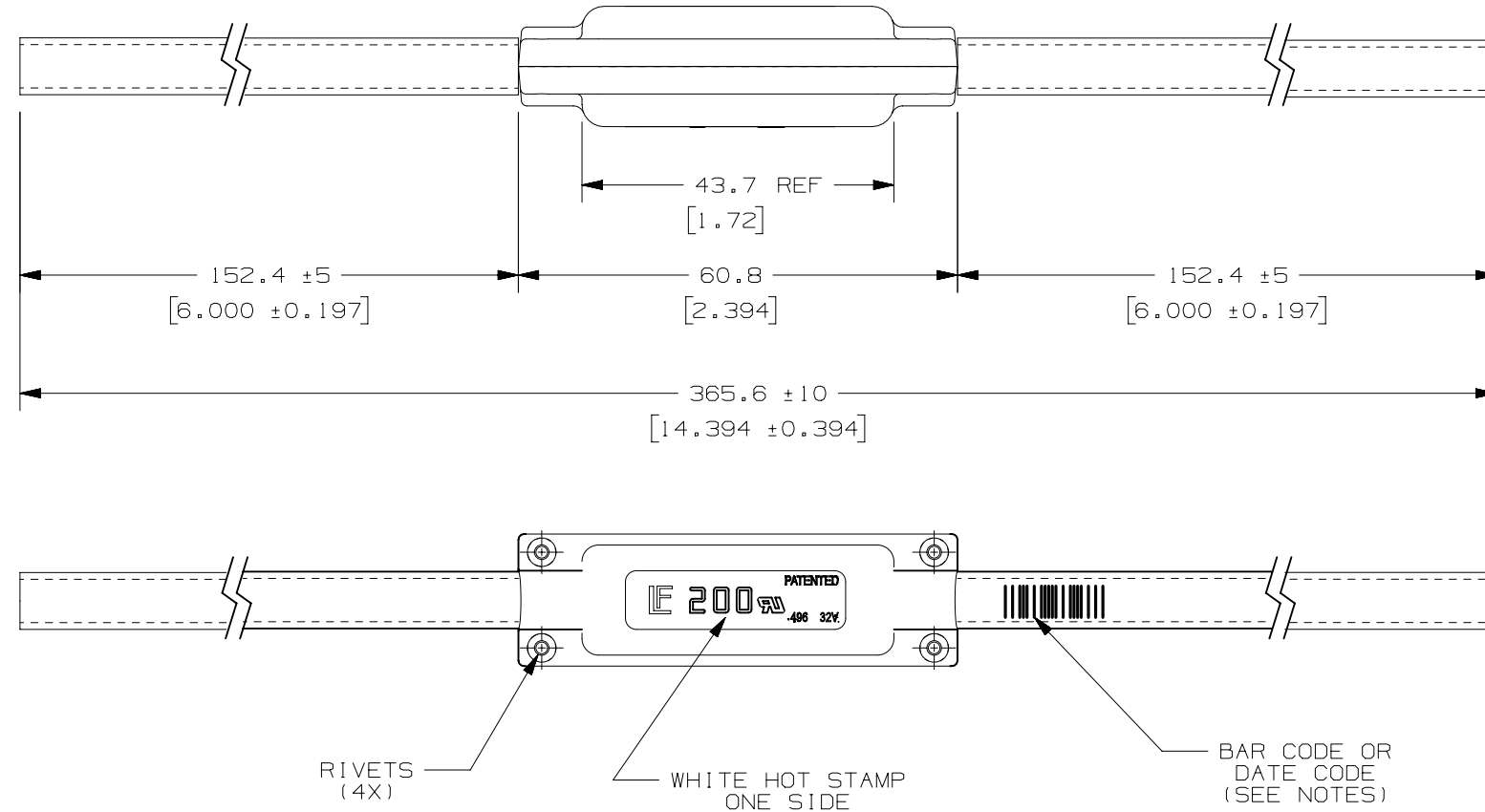

METRIC

ASSEMBLY

[illegible]