


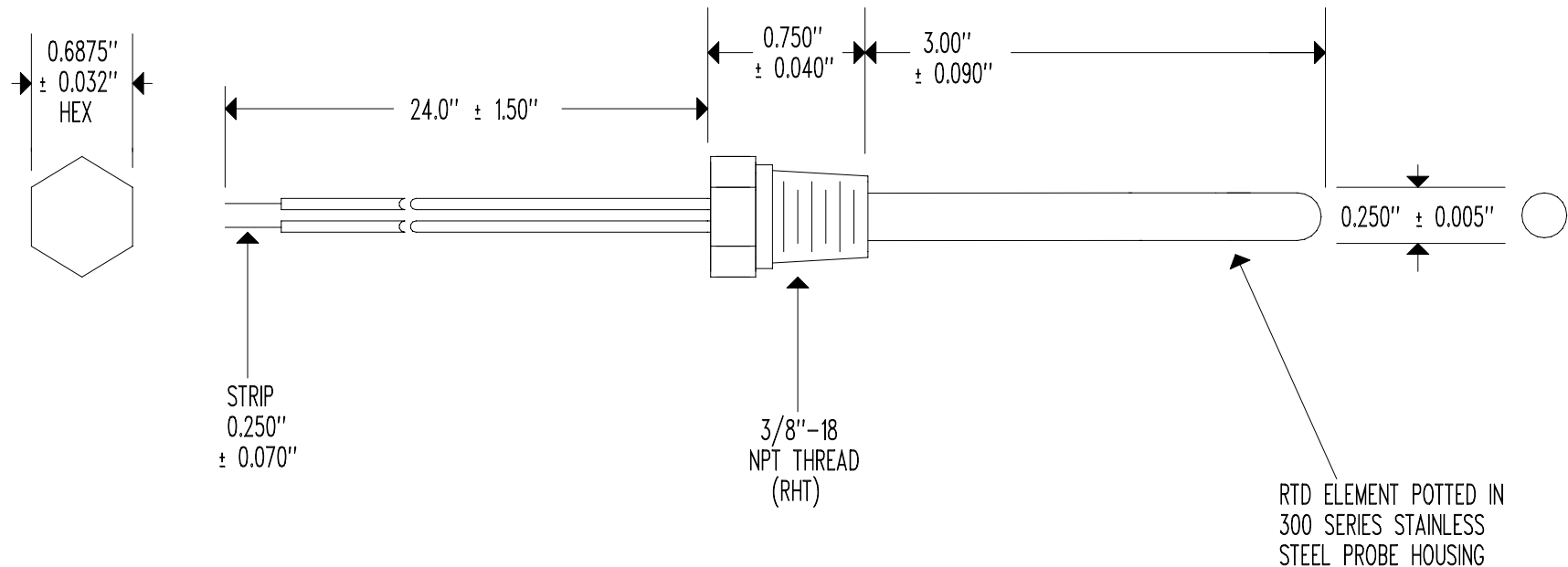

RTD ELEMENT RESISTANCE @ 0°C = 1,000 Ω ± 0.06%
 RTD ELEMENT ACCURACY @ 0°C = ± 0.15°C
 TCR = 3,850ppm/°C
 RTD ELEMENT DIN 43760 ACCURACY CLASS = "A"
 MAXIMUM TEMPERATURE RATING = +105°C

LEAD WIRES: 24 AWG, STRANDED CONDUCTOR, SINGLE CONDUCTOR,
 PVC INSULATED, INSULATION COLOR: BLACK

MOISTURE RESISTANT PROBE ASSEMBLY

*** ROHS COMPLIANT ***

SEE MANUFACTURING SPECIFICATION (LAYER 1)

NONE	RELEASE TO PRODUCTION	07/31/13	DD
REV	REVISION RECORD	DATE	APP

SCALE	NONE	© COPYRIGHT U.S. SENSOR CORP. 714-639-1000 www.ussensor.com	
DRAWN BY	DAN DANKERT		
DATE	07/31/13	RTD PROBE ASSY	
REV.	NONE	P/N USW3483	
LAYER	0 OF 2		