


Specialized Toggle Switches

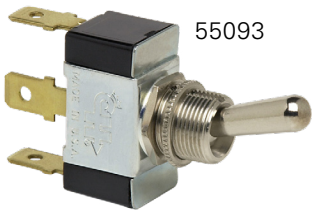

55093



M-597



55015-03



5543

Description

Littelfuse Specialized Toggle Switches stand out as a robust and versatile choice for universal applications in challenging environments. Featuring specialized options with non-traditional geometries, catering to unique applications. The switches support a voltage range of 12V to 30V DC, making them compatible with various electrical systems. Offering Single Pole Double Throw (SPDT), Single Pole Single Throw (SPST), and Double Pole Double Throw (DPDT) circuitry options, along with ingress protection features, Littelfuse Toggle Switches provide a comprehensive solution for diverse electrical setups, ensuring optimal performance in demanding conditions.

Ordering Information

Specifications

Max Voltage (V DC):	12V-30V DC
Circuitry:	SPDT, SPST, DPDT
Input Terminals:	2-6 Blade, 2 Leads
Actuator:	Standard, Long, Wedge
Actuator Details:	Playted Brass
Panel Thickness:	Up to 1/4 (6.35mm) thick
Contact Material:	Silver

Applications

- Construction Equipment
- Agricultural Equipment
- Material Handling Equipment
- Commercial Vehicles

Web Resources

Download 2D print, installation guide and technical resources at: [Littelfuse.com/SpecializedToggleSwitches](https://www.littelfuse.com/SpecializedToggleSwitches)

PART NUMBER	AMPS	VOLTS	CIRCUITRY	INGRESS	POSITIONS	INPUT TERMINALS	HOUSING	ACTUATOR	MOUNTING METHOD
55015-03	25	12	SPDT	-	On (Off) - None - On	3 Blade	Black Plastic with Plated Steel Cap	Standard Toggle	Plated Steel Hex Nut
55015-03-BX	25	12	SPDT	-	On (Off) - None - On	3 Blade		Standard Toggle	Plated Steel Hex Nut
55046-03	15	24	DPDT	-	Momentary On - Off - Momentary On	4 Blade		Standard Toggle	Plated Steel Hex Nut
55046-11	25	12	DPDT	-	-	-		Standard Toggle	Nickel Plated Brass
55064	25	12	DPDT	-	Park Tail Headlamps - Off - Park Tail Auxiliary Lamps	6 Blade		Standard / Long	Plated Steel Hex Nut
55071	25	12	DPDT	-	Momentary Off - On - On	3 Blade		Standard Toggle	Plated Steel Hex Nut
55093	25	12	DPDT	-	Battery Hi - Battery Low - Off	3 Blade		Standard Toggle	Nickel Plated Brass Face Nut
55093-BX	25	12	DPDT	-	Battery Hi - Battery Low - Off	3 Blade		Standard Toggle	Nickel Plated Brass
5543	10	12	SPST	-	On - None - Off	2 Blade		Standard Toggle	Nickel Plated Brass
59071	20	12	DPDT		Off - Ignition - Momentary On	4 Blade		Wedge Toggle	Nickel Plated Brass Face Nut
M-597	10	12	SPST	IP66	On - None - Momentary On	2 Leads (197.66mm 16AWG Stripped)	Black Plastic with Plated Steel Cap Hencol Sealing	Standard Toggle	Nickel Plated Brass Face and Hex Nut
M-597-BP	10	12	SPST	IP66	On - None - Momentary On	2 Leads (197.66mm 16AWG Stripped)	Black Plastic with Plated Steel Cap Hencol Sealing	Standard Toggle	Black Finished Face Nut
00900400	8	30	SPST		On-Off	3 Blade	Black Plastic Black Rubber Cap	Standard Toggle	Black Finished Face Nut
00900900	250	24	SPDT	IP67/IP69K	On-Mom	3 Blade	Black Plastic Red Rubber Cap	Standard Toggle	Nickel Plated Brass