


GROUND-FAULT-CT SELECTION FLOWCHART

Applicable Monitors: MPU-32, MPS, SE-330, SE-701, SE-703, FPU-32

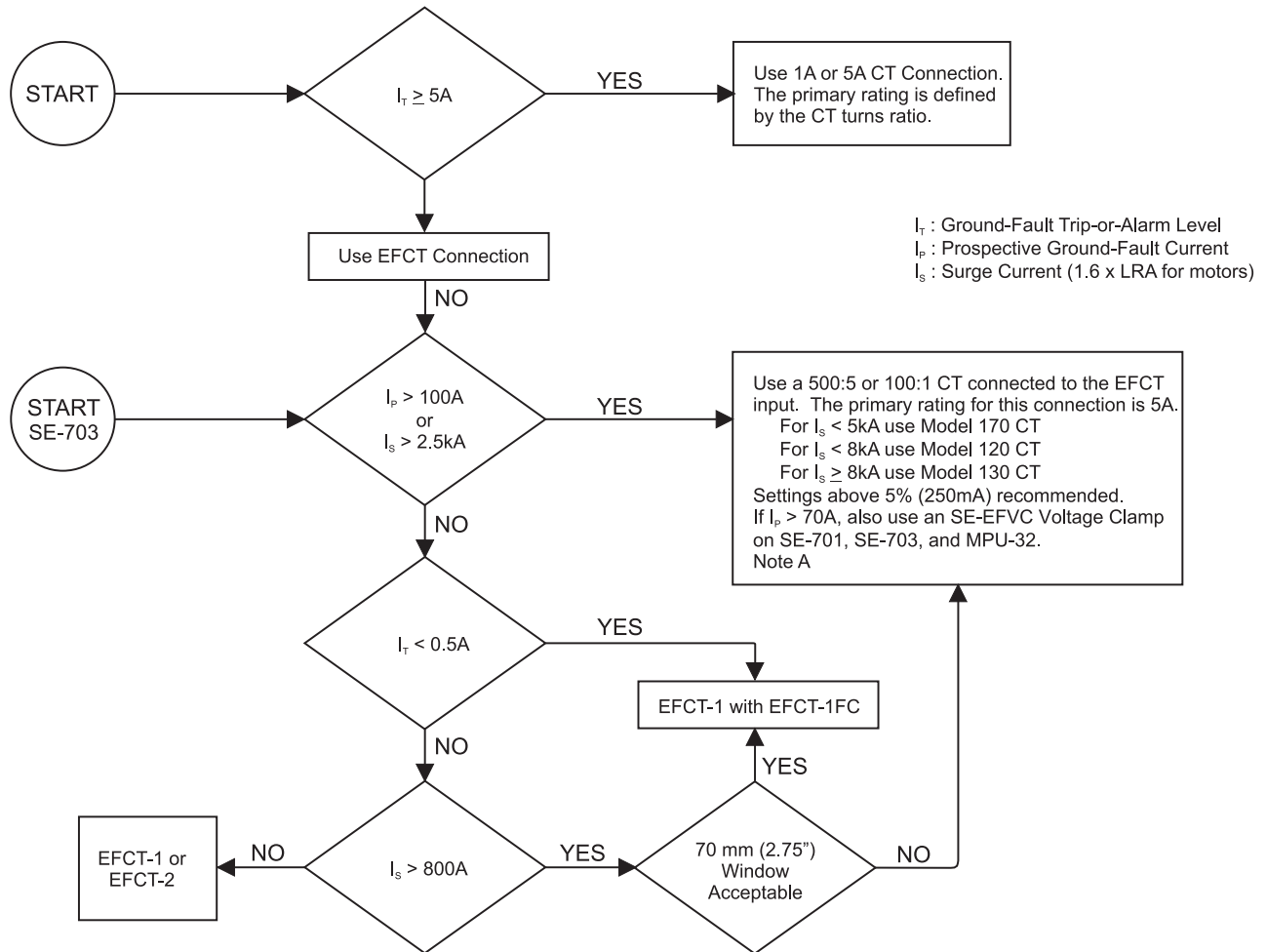

- Note A: 120-501: 500:5 Model 120 CT, 146mm (5.75") Window, 5 kg (11 lb)
 130-501: 500:5 Model 130 CT, 146 mm (5.75") Window, 8.2 kg (18 lb)
 170SHT-501: 500:5 Model 170 CT, 108 mm (4.25") Window, 1.4 kg (3 lb)
 Other 500:5 or 100:1 CTs may work but the user should test to verify performance.
- Note B: EFCT-1: CT with no flux conditioner, 82 mm (3.23") Window.
 EFCT-1FC: EFCT-1 flux conditioner, 70 mm (2.75") Window.
 EFCT-2: CT complete with flux conditioner, 140 mm (5.50") Window.

See Monitoring Neutral-Grounding Resistor paper for ground-fault settings in resistance-grounded applications.