


RATINGS

MAXIMUM VOLTAGE	8,400 Vac
MAXIMUM CURRENT	84 mA
RESISTANCE	100 kΩ
THERMAL	
8,400 Vac	1 MINUTE ON, 120 MINUTES OFF CONTINUOUS
1,900 Vac	
TORQUE	
TERMINAL N	9.0 N-m (80 in-lb)

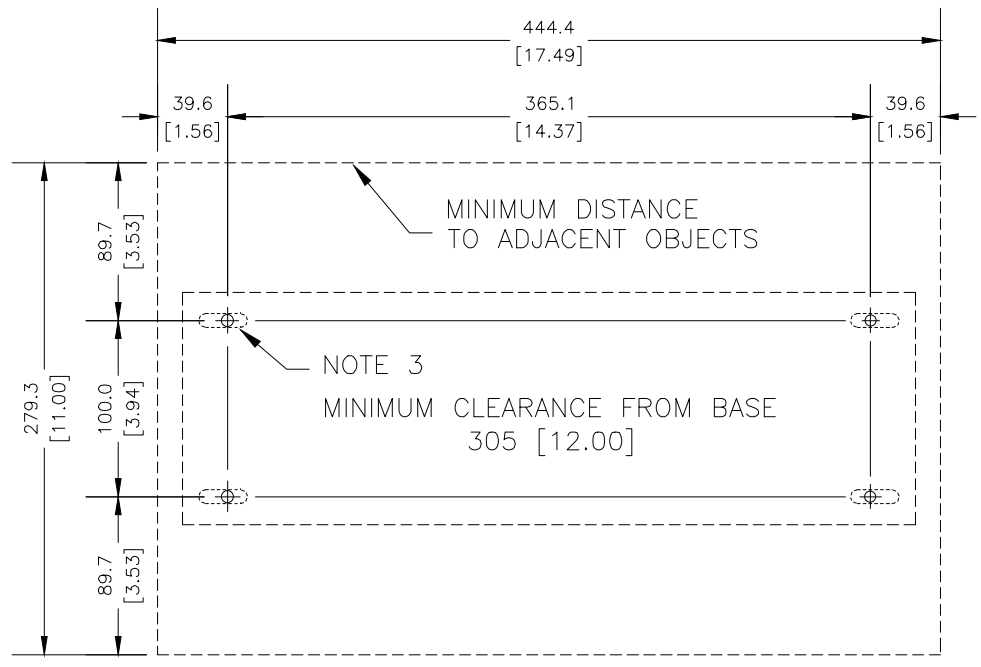

- NOTES**
1. DIMENSIONS IN MILLIMETERS [INCHES]
 2. TERMINAL-BLOCK SCREWS: 6-32 x 0.25.
 3. MOUNTING SCREWS: M6 OR 0.25-20.
 4. USE LIQUID-TIGHT FITTING FOR TERMINAL-BLOCK-ENCLOSURE CABLE ENTRY.
 5. CERTIFICATIONS NOT SHOWN.