



MINI® Smart Glow Blade Fuse

Smart Glow fuses are innovative automotive style fuses that feature an indicator light that glows when the fuse is blown, saving time to troubleshoot an open circuit.


Interrupting Rating: 1000A @32VDC

Voltage Rating: 32 VDC

Operating Temperature Range: -40°C to +125°C

Terminals: Tin plated Zinc alloy


DIMENSIONS

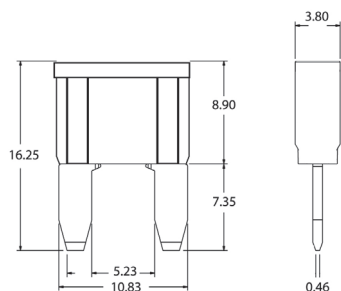


TIME-CURRENT CHARACTERISTICS

% of Rating	Opening Time Min / Max (s)
110	360,000 s / -
135	0.75 s / 600 s
200	0.15 s / 5 s
350	0.080 s / 0.250 s
600	0.030 s / 0.100 s

TIME-CURRENT CHARACTERISTIC CURVES

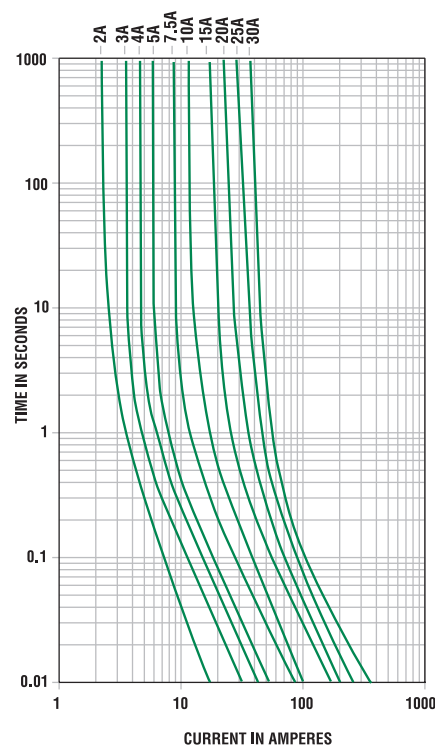

TEMPERATURE DERATING CURVE

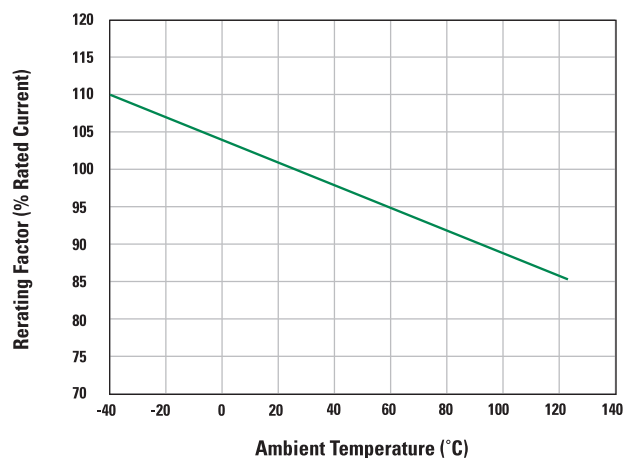

MINI® FUSE TABLE

COLOR CODE	CURRENT RATING (A)	CARDED	
		MATERIAL #	CATALOG #
Gray	2A	---	---
Violet	3A	OMIN003.VPGLO	11-0003
Pink	4A	---	---
Tan	5A	OMIN005.VPGLO	11-1000
Brown	7.5A	OMIN07.5VPGLO	11-0007
Red	10A	OMIN010.VPGLO	11-1001
Blue	15A	OMIN015.VPGLO	11-1002
Yellow	20A	OMIN020.VPGLO	11-1003
Clear	25A	OMIN025.VPGLO	11-1004
Green	30A	OMIN030.VPGLO	11-1005



**SMART
GLOW Fuse**