

08010200 BATTERY DISCONNECT SWITCHES

250A • SPST • IP65 • M10 Studs • Fixed T-Handle



Description

Manual Battery Disconnect Switch features a plastic fixed T-handle and corrosion protected aluminum body designed to be used in harsh environment. Compatible as a cross reference to competitive products in the market. 250A single pole battery switch with M10 Studs.

Features/Benefits

- 250A continuous current rating
- Highly visible bright red T-handle
- Compatible with competitive products
- Waterproof and dustproof to IP65

Specifications

Max Operating Voltage:	24V DC
Max Continuous Current:	250A
Intermittent Current:	2000A at 3 sec
Operating Temp:	-40°C to +80°C
Ingress Protection:	IP65
Contacts:	Silver Plated Copper
Terminals:	M10 (zinc-plated steel)


Applications

- Heavy Truck
- Off-Road
- Emergency Vehicles
- Material Handling
- Mining
- Agricultural
- Marine
- Construction

Web Resources

Download 2D prints and additional technical resources at:
littelfuse.com/ManualBatterySwitches

Electrical Diagram

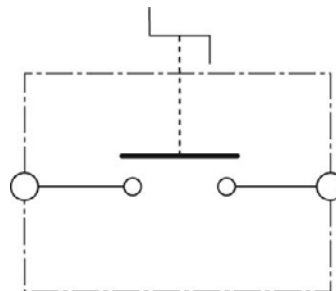

Ordering Information

PART NUMBERS		VOLTAGE	AMPERAGE	CIRCUITRY	MOUNTING	INGRESS	NOTES
BULK	BOXED						
08010200	08010200-BX	24V DC	250A	SPST	Surface Mount	IP65	—

Dimensions in inches (millimeters)

