



**356/359 Screw Terminal Laminated Base Terminal for 3AG/AB Fuses**

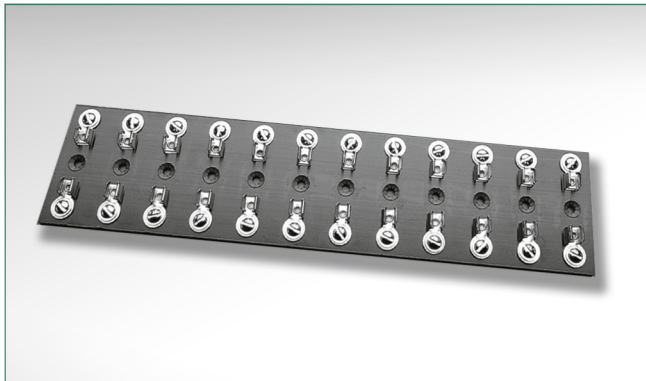

**Dimensions**

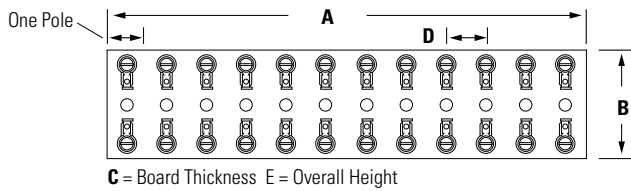

Fuse Type	A	B	C	D	E
3AG/3AB	See ordering information	2.38" [60.5 mm]	.25" [6.4 mm]	.91" [23.1 mm]	.73" [18.5 mm]

**Additional Information**

**356 Series**



**Resources  
356 Series**



**Samples  
356 Series**

**359 Series**



**Resources  
359 Series**



**Samples  
359 Series**

**Product Characteristics**

<b>Compatible Fuse Size</b>	<b>3AG/AB</b>
<b>Electical</b>	356 Series: 600 Vac/dc 15 A 359 Series: 600 Vac/dc 30 A
<b>Clip/Terminals</b>	356 000 Series: Nickel-plated spring brass 359 000 Series: Silver-plated beryllium copper
<b>Terminals</b>	B-32THD screw type
<b>Base</b>	Black phenolic laminate.
<b>Mounting Hole</b>	3AG Block: Reference Dimensions .142"/.147" [3.6/3.7 mm] diameter with .295"/.302" [7.5/7.7 mm] x82" [20.8 mm] C.S.
<b>Operation Temperature</b>	-40 °C to +125 °C

**Agency Approvals**

Agency	Agency File Number
	E14721

**Ordering Information**

# of Poles	Dimension "A" [mm]	Ordering Number	
1	.78" [19.8]	<b>03560001Z</b>	<b>03590001Z</b>
2	1.69" [42.9]	<b>03560002Z</b>	<b>03590002Z</b>
3	2.59" [65.8]	<b>03560003Z</b>	<b>03590003Z</b>
4	3.50" [88.9]	<b>03560004Z</b>	<b>03590004Z</b>
5	4.41" [112.0]	<b>03560005Z</b>	<b>03590005Z</b>
6	5.31" [134.9]	<b>03560006Z</b>	<b>03590006Z</b>
7	6.21" [157.7]	<b>03560007Z</b>	<b>03590007Z</b>
8	7.12" [180.8]	<b>03560008Z</b>	<b>03590008Z</b>
9	8.03" [204.0]	<b>03560009Z</b>	<b>03590009Z</b>
10	8.94" [227.1]	<b>03560010Z</b>	<b>03590010Z</b>
11	9.84" [250.0]	<b>03560011Z</b>	<b>03590011Z</b>
12	10.75" [273.1]	<b>03560012Z</b>	<b>03590012Z</b>