



356/359 Screw Terminal Laminated Base Terminal for 3AG/AB Fuses

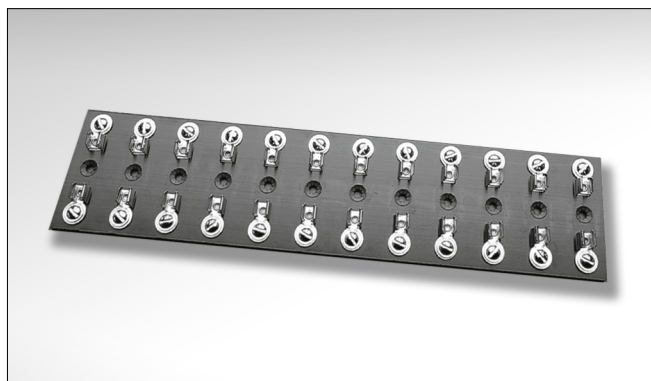

Dimensions

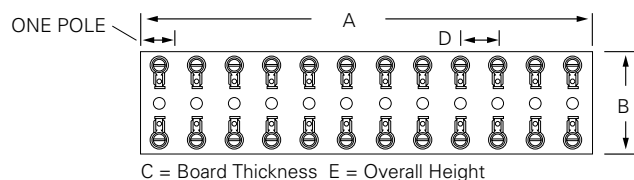

Fuse Type	A	B	C	D	E
3AG/3AB	See ordering information	2.38" [60.5mm]	.25" [6.4mm]	.91" [23.1mm]	.73" [18.5mm]


Additional Information

356 Series		
	356 Series	356 Series
359 Series		
	359 Series	359 Series

Product Characteristics

Compatible Fuse Size	3AG/AB
Electical	356 Series Rated at 15 Amp. / 600 V AC/DC 359 Series rated at 30 Amp. / 600 V AC/DC
Clip/Terminals	356 000 Series: Nickel-plated spring brass 359 000 Series: Silver-plated beryllium copper
Terminals	B-32THD screw type
Base	Black phenolic laminate.
Mounting Hole	3AG Block: Reference Dimensions .142"/.147" [3.6/3.7mm] diameter with .295"/.302" [7.5/7.7mm] x82" [20.8mm] C.S.

Agency Approvals

Agency	Agency File Number
	E14721

Ordering Information

# of Poles	Dimension "A" [mm]	Ordering Number	
1	.78" [19.8]	03560001Z	03590001Z
2	1.69" [42.9]	03560002Z	03590002Z
3	2.59" [65.8]	03560003Z	03590003Z
4	3.50" [88.9]	03560004Z	03590004Z
5	4.41" [112.0]	03560005Z	03590005Z
6	5.31" [134.9]	03560006Z	03590006Z
7	6.21" [157.7]	03560007Z	03590007Z
8	7.12" [180.8]	03560008Z	03590008Z
9	8.03" [204.0]	03560009Z	03590009Z
10	8.94" [227.1]	03560010Z	03590010Z
11	9.84" [250.0]	03560011Z	03590011Z
12	10.75" [273.1]	03560012Z	03590012Z

Disclaimer Notice - Information furnished is believed to be accurate and reliable. However, users should independently evaluate the suitability of and test each product selected for their own applications. Littelfuse products are not designed for, and may not be used in, all applications. Read complete Disclaimer Notice at: www.littelfuse.com/disclaimer-electronics.